

Part No: 4723L1-025C

Valves

3-Way Ball Valve

Desc: 2-1/2 CPVC T/U IND 3WY VERT L/1 FLG EPDM

MSRP: 3600.44

Part Code: 617

Weight(lbs): 14.784


Weight(kg): 6.706

Weight(gm): 6706

Size: 2-1/2

Color: GRAY

Material: CPVC

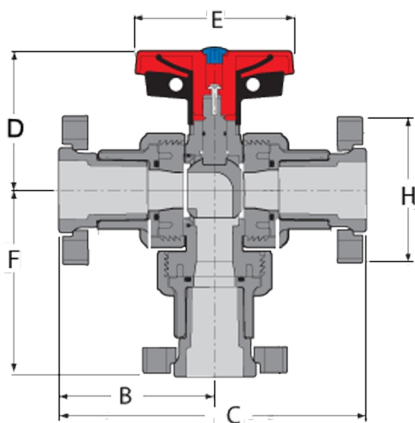

A = 5- 3/8

B = 5- 7/8

C = 9- 5/16

D = 5- 1/8

E = 6- 1/4

G = 4- 3/8

F = 7- 3/16

H = 7- 1/2

Type Single L - Port (Vertical)

Connection Flanged

O-Ring EPDM

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

