

Part No: 4723L2-020C

Valves

3-Way Ball Valve

Desc: 2 CPVC T/U IND 3WAY VERT L/2 FLG EPDM

MSRP: 2238.69

Part Code: 617

Weight(lbs): 5.939


Weight(kg): 2.694

Weight(gm): 2694

Size: 2

Color: GRAY

Material: CPVC

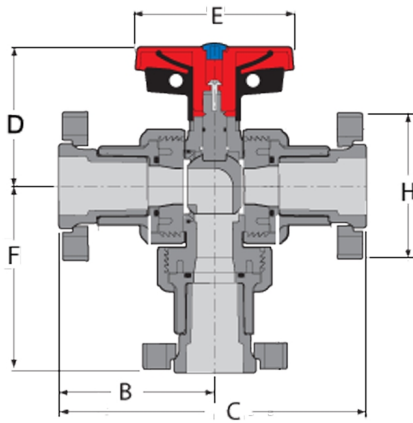

B = 4- 3/4

C = 7- 3/4

D = 4- 1/2

E = 5- 1/8

F = 6- 3/8

H = 6

Type Double L - Port (Vertical)
Connection Flanged
O-Ring EPDM

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

