

Part No: 4723L2-030C

Valves

3-Way Ball Valve

Desc: 3 CPVC T/U IND 3WAY VERT L/2 FLG EPDM

MSRP: 3911.76

Part Code: 617

Weight(lbs): 13.951


Weight(kg): 6.328

Weight(gm): 6328

Size: 3

Color: GRAY

Material: CPVC

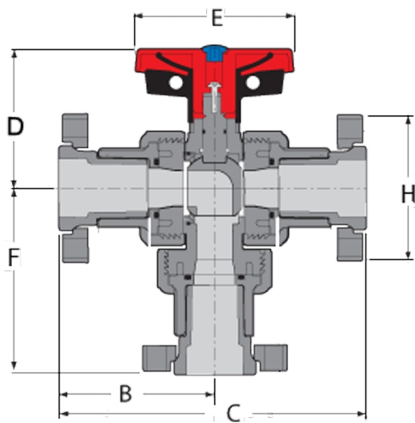

B = 6- 7/8

C = 10-11/16

D = 5- 7/8

E = 7- 5/8

F = 8-1/8

H = 7-1/2

Type Double L - Port (Vertical)

Connection Flanged

O-Ring EPDM

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

