

**Part No:** 4723L3-007

**Valves**

**3-Way Ball Valve**

**Desc:** 3/4 PVC T/U IND 3WAY VERT L/3 FLG EPDM

**MSRP:** 541.73

**Part Code:** 615

**Weight(lbs):** 1.671


**Weight(kg):** 0.758

**Weight(gm):** 758

**Size:** 3/4

**Color:** GRAY

**Material:** PVC

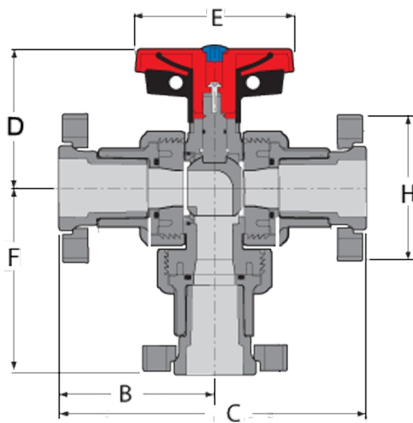

**B** = 2- 3/4

**C** = 4- 3/4

**D** = 2- 7/8

**E** = 3- 5/16

**F** = 3-15/16

**H** = 3-7/8

**Type** Triple L - Port (Vertical)  
**Connection** Flanged  
**O-Ring** EPDM

## Injection Molded Dimension References:

**G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses;  $\pm 1/32$  inch.

**H** = Intersection of center lines to face of fitting; 90° elbows tees, crosses;  $\pm 1/32$  inch.

**J** = Intersection of center lines to bottom of socket/thread; 45° elbows;  $\pm 1/32$  inch

**L** = Overall length of fittings;  $\pm 1/16$  inch.

**M** = Outside diameter of socket/thread hub;  $\pm 1/16$  inch.

**N** = Socket bottom to socket bottom; couplings;  $\pm 1/16$  inch.

**W** = Height of cap;  $\pm 1/16$  inch

## Typical Molded Dimension References

