

Part No: 4723L3-007C

Valves

3-Way Ball Valve

Desc: 3/4 CPVC T/U IND 3WAY VERT L/3 FLG EPDM

MSRP: 833.24

Part Code: 617

Weight(lbs): 1.739


Weight(kg): 0.789

Weight(gm): 789

Size: 3/4

Color: GRAY

Material: CPVC

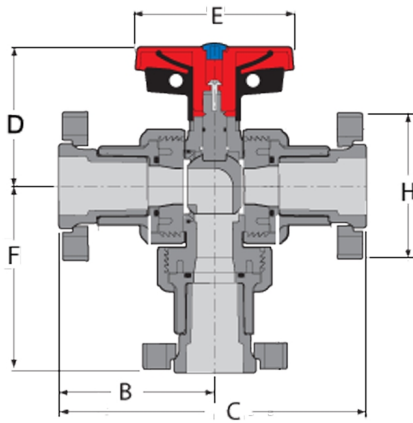

B = 2- 3/4

C = 4- 3/4

D = 2- 7/8

E = 3- 5/16

F = 3-15/16

H = 3-7/8

Type Triple L - Port (Vertical)
Connection Flanged
O-Ring EPDM

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

