

Part No: 4723L3-015C

Valves

3-Way Ball Valve

Desc: 1-1/2 CPVC T/U IND 3WY VERT L/3 FLG EPDM

MSRP: 1856.34

Part Code: 617

Weight(lbs): 3.88


Weight(kg): 1.76

Weight(gm): 1760

Size: 1-1/2

Color: GRAY

Material: CPVC

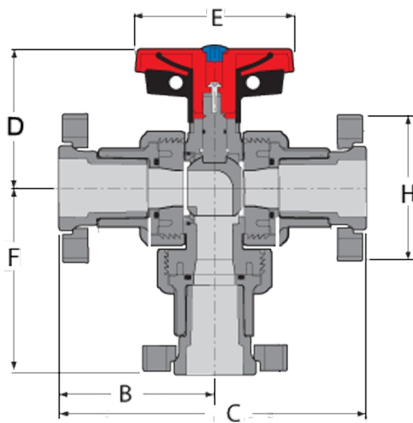

B = 3- 1/2

C = 6- 1/4

D = 4

E = 4- 3/16

F = 4-13/16

H = 5

Type Triple L - Port (Vertical)
Connection Flanged
O-Ring EPDM

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

