

Part No: 4723T1-005

Valves

3-Way Ball Valve

Desc: 1/2 PVC T/U IND 3WAY VERT T/PT FLG EPDM

MSRP: 354.09

Part Code: 615

Weight(lbs): 1.122


Weight(kg): 0.509

Weight(gm): 509

Size: 1/2

Color: GRAY

Material: PVC

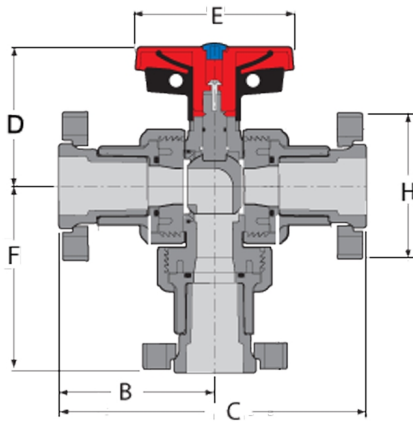

B = 2- 7/16

C = 4- 3/16

D = 2- 9/16

E = 2-13/16

F = 4-11/32

H = 3-1/2

Type T - Port (Vertical)

Connection Flanged

O-Ring EPDM

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

