

Part No: 4723T1-040C

Valves

3-Way Ball Valve

Desc: 4 CPVC T/U IND 3WAY VERT T/PT FLG EPDM

MSRP: 5359.4

Part Code: 617

Weight(lbs): 26.264


Weight(kg): 11.913

Weight(gm): 11913

Size: 4

Color: GRAY

Material: CPVC

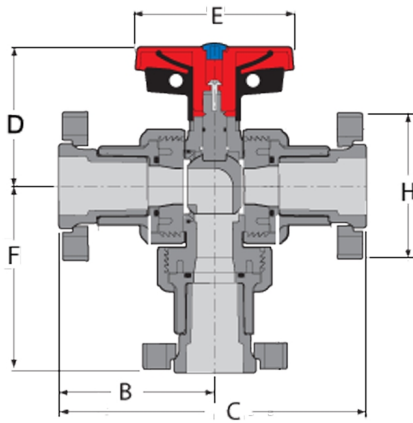

B = 7- 1/4

C = 11-13/16

D = 6- 3/4

E = 9- 3/16

F = 8-7/8

H = 9

Type T - Port (Vertical)
Connection Flanged
O-Ring EPDM

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

