

Part No: 4727L1-010C

Valves

3-Way Ball Valve

Desc: 1 CPVC T/U IND 3WAY VERT L/I SPG EPDM

MSRP: 375.88

Part Code: 617

Weight(lbs): 1.155


Weight(kg): 0.524

Weight(gm): 524

Size: 1

Color: GRAY

Material: CPVC

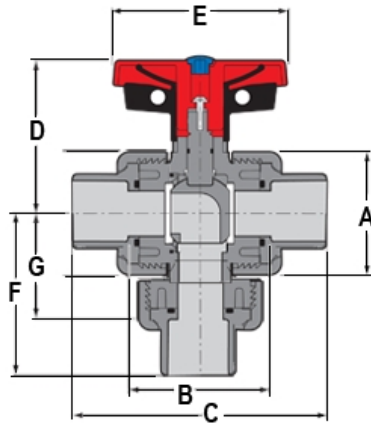

G = 2- 1/8

A = 2- 9/16

B = 2- 7/8

C = 5-3/4

D = 3- 1/8

E = 3- 7/16

F = 3-9/16

Type Single L - Port (Vertical)
Connection Spigot
O-Ring EPDM

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

