

Part No: 4727L1-015C

Valves

3-Way Ball Valve

Desc: 1-1/2 CPVC T/U IND 3WY VERT L/1 SPG EPDM

MSRP: 525.66

Part Code: 617

Weight(lbs): 2.363


Weight(kg): 1.072

Weight(gm): 1072

Size: 1-1/2

Color: GRAY

Material: CPVC

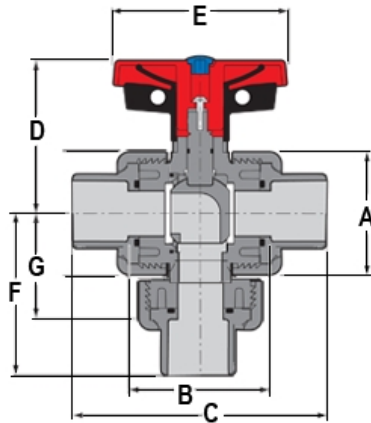

G = 2- 9/16

A = 3- 1/2

B = 3- 1/2

C = 6-3/4

D = 4

E = 4- 3/16

F = 4-1/2

Type Single L - Port (Vertical)
Connection Spigot
O-Ring EPDM

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

