

**Part No:** 4727L1-020C

**Valves**

**3-Way Ball Valve**

**Desc:** 2 CPVC T/U IND 3WAY VERT L/I SPG EPDM

**MSRP:** 645

**Part Code:** 617

**Weight(lbs):** 4.087


**Weight(kg):** 1.854

**Weight(gm):** 1854

**Size:** 2

**Color:** GRAY

**Material:** CPVC

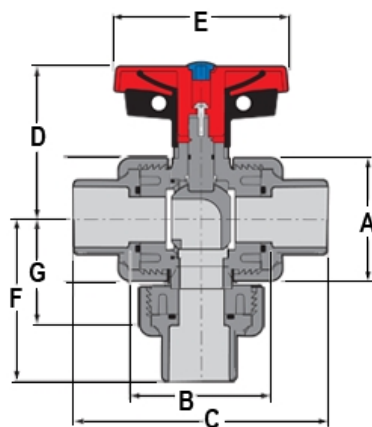

**A** = 4- 1/4

**B** = 4- 3/4

**C** = 8-1/4

**D** = 4- 1/2

**E** = 5- 1/8

**F** = 5-5/16

**G** = 3- 1/2

**Type** Single L - Port (Vertical)  
**Connection** Spigot  
**O-Ring** EPDM

## Injection Molded Dimension References:

**G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses;  $\pm 1/32$  inch.

**H** = Intersection of center lines to face of fitting; 90° elbows tees, crosses;  $\pm 1/32$  inch.

**J** = Intersection of center lines to bottom of socket/thread; 45° elbows;  $\pm 1/32$  inch

**L** = Overall length of fittings;  $\pm 1/16$  inch.

**M** = Outside diameter of socket/thread hub;  $\pm 1/16$  inch.

**N** = Socket bottom to socket bottom; couplings;  $\pm 1/16$  inch.

**W** = Height of cap;  $\pm 1/16$  inch

## Typical Molded Dimension References

