

**Part No:** 4727L2-005C

**Valves**

**3-Way Ball Valve**

**Desc:** 1/2 CPVC T/U IND 3WAY VERT L/2 SPG EPDM

**MSRP:** 525.11

**Part Code:** 617

**Weight(lbs):** 0.553


**Weight(kg):** 0.251

**Weight(gm):** 251

**Size:** 1/2

**Color:** GRAY

**Material:** CPVC

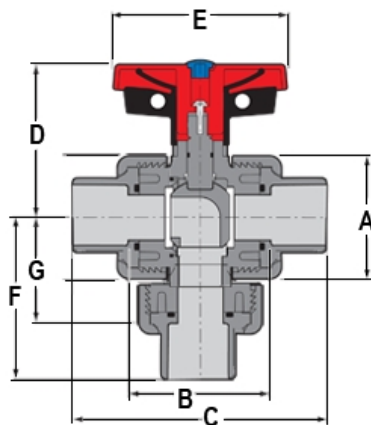

**A** = 1- 7/8

**B** = 2- 7/16

**C** = 4-3/4

**D** = 2- 9/16

**E** = 2-13/16

**F** = 2-13/16

**G** = 1-11/16

**Type** Double L - Port (Vertical)

**Connection** Spigot

**O-Ring** EPDM

## Injection Molded Dimension References:

**G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses;  $\pm 1/32$  inch.

**H** = Intersection of center lines to face of fitting; 90° elbows tees, crosses;  $\pm 1/32$  inch.

**J** = Intersection of center lines to bottom of socket/thread; 45° elbows;  $\pm 1/32$  inch

**L** = Overall length of fittings;  $\pm 1/16$  inch.

**M** = Outside diameter of socket/thread hub;  $\pm 1/16$  inch.

**N** = Socket bottom to socket bottom; couplings;  $\pm 1/16$  inch.

**W** = Height of cap;  $\pm 1/16$  inch

## Typical Molded Dimension References

