

Part No: 4727L3-012

Valves

3-Way Ball Valve

Desc: 1-1/4 PVC T/U IND 3WAY VERT L/3 SPG EPDM

MSRP: 465.49

Part Code: 615

Weight(lbs): 1.709


Weight(kg): 0.775

Weight(gm): 775

Size: 1-1/4

Color: GRAY

Material: PVC

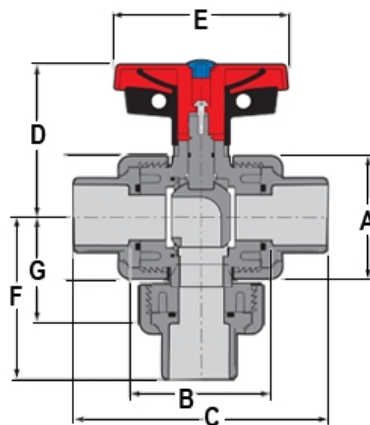

A = 3- 1/16

B = 3- 1/4

C = 6-5/16

D = 3- 5/8

E = 3-13/16

F = 4-1/16

G = 2- 3/8

Type Triple L - Port (Vertical)

Connection Spigot

O-Ring EPDM

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

