

Part No: 4727L3-025C

Valves

3-Way Ball Valve

Desc: 2-1/2 CPVC T/U IND 3WY VERT L/3 SPG EPDM

MSRP: 2529.58

Part Code: 617

Weight(lbs): 10.064


Weight(kg): 4.565

Weight(gm): 4565

Size: 2-1/2

Color: GRAY

Material: CPVC

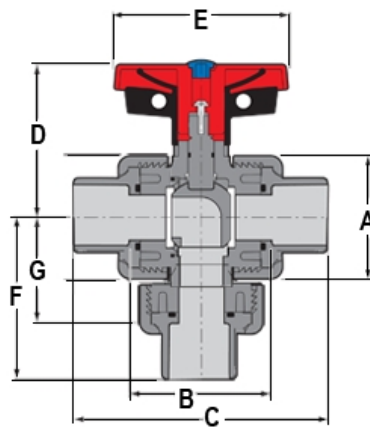

A = 6-3/16

B = 8-1/8

C = 11-5/8

D = 5-7/8

E = 7-5/8

F = 7-1/16

G = 5-5/16

Type Triple L - Port (Vertical)
Connection Spigot
O-Ring EPDM

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

