

Part No: 4731L1-015CSR

Valves

3-Way Ball Valve

Desc: 1-1/2 CPVC T/U IND 3WY VRT L/1 SRTHD FKM

MSRP: 610.03

Part Code: 617

Weight(lbs): 2.399


Weight(kg): 1.088

Weight(gm): 1088

Size: 1-1/2"

Color: GRAY

Material: CPVC

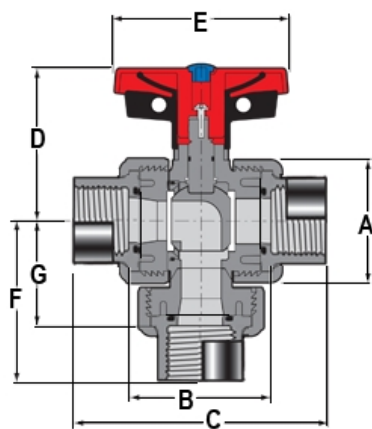

A = 3- 1/2

B = 3- 1/2

C = 5- 7/16

D = 4

E = 4- 3/16

F = 3-13/16

G = 2- 9/16

Type Single L - Port (Vertical)

Connection SR Fipt

O-Ring FKM

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

