

Part No: 4731L2-015SR

Valves

3-Way Ball Valve

Desc: 1-1/2 PVC T/U IND 3WAY VRT L2 SR/THD FKM

MSRP: 566.41

Part Code: 615

Weight(lbs): 2.328


Weight(kg): 1.056

Weight(gm): 1056

Size: 1-1/2"

Color: GRAY

Material: PVC

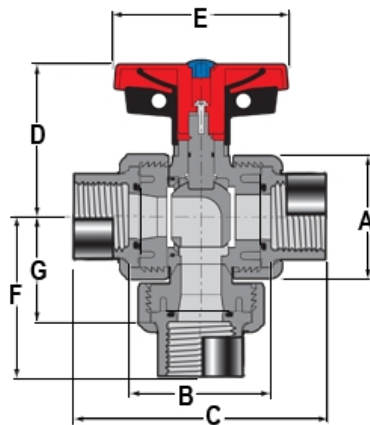

A = 3- 1/2

B = 3- 1/2

C = 5- 7/16

D = 4

E = 4- 3/16

F = 3-13/16

G = 2- 9/16

Type Double L - Port (Vertical)
Connection SR Fipt
O-Ring FKM

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References



The information printed here is based on current information & product design at the time of publication and is subject to change without notification. Spears® ongoing commitment to product improvement may result in some variation. No representation, guarantees or warranties of any kind are as to its accuracy, suitability for particular application or results to be obtained therefrom. For verification of technical data or additional information, please contact Spears® Technical Service Department :: WEST COAST : (818) 364-1611 - EAST COAST : (717) 938-9006