

Part No: 4731L3-012CSR

Valves

3-Way Ball Valve

Desc: 1-1/4 CPVC T/U IND 3WY VRT L/3 SRTHD FKM

MSRP: 819.52

Part Code: 617

Weight(lbs): 1.777


Weight(kg): 0.806

Weight(gm): 806

Size: 1-1/4"

Color: GRAY

Material: CPVC

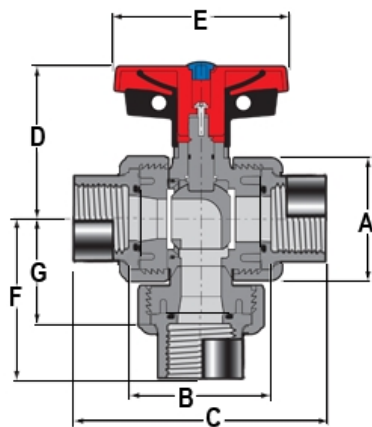

A = 3- 1/16

B = 3- 1/4

C = 5- 3/16

D = 3- 5/8

E = 3-13/16

F = 3- 7/16

G = 2- 3/8

Type Triple L - Port (Vertical)

Connection SR Fipt

O-Ring FKM

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

