

Part No: 4731L3-012SR

Valves

3-Way Ball Valve

Desc: 1-1/4 PVC T/U IND 3WY VRT L/3 SR/THD FKM

MSRP: 531.81

Part Code: 615

Weight(lbs): 1.715


Weight(kg): 0.778

Weight(gm): 778

Size: 1-1/4"

Color: GRAY

Material: PVC

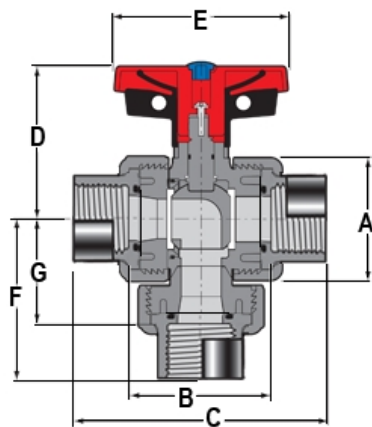

A = 3- 1/16

B = 3- 1/4

C = 5- 3/16

D = 3- 5/8

E = 3-13/16

F = 3- 7/16

G = 2- 3/8

Type Triple L - Port (Vertical)

Connection SR Fipt

O-Ring FKM

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

