

Part No: 4731L3-025SR

Valves

3-Way Ball Valve

Desc: 2-1/2 PVC T/U IND 3WY VRT L/3 SR/THD FKM

MSRP: 1721.97

Part Code: 615

Weight(lbs): 9.595


Weight(kg): 4.352

Weight(gm): 4352

Size: 2-1/2"

Color: GRAY

Material: PVC

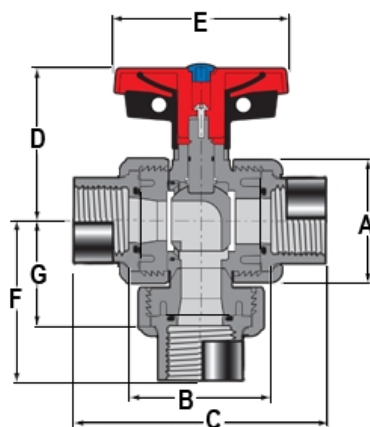

A = 6-3/16

B = 7-1/8

C = 9-7/8

D = 5-7/8

E = 7-5/8

F = 6-1/4

G = 4-7/8

Type Triple L - Port (Vertical)

Connection SR Fipt

O-Ring FKM

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

