

Part No: 4731L3-040SR

Valves

3-Way Ball Valve

Desc: 4 PVC T/U IND 3WAY VERT L/3 SR/THD FKM

MSRP: 2865.9

Part Code: 615

Weight(lbs): 17.577


Weight(kg): 7.973

Weight(gm): 7973

Size: 4"

Color: GRAY

Material: PVC

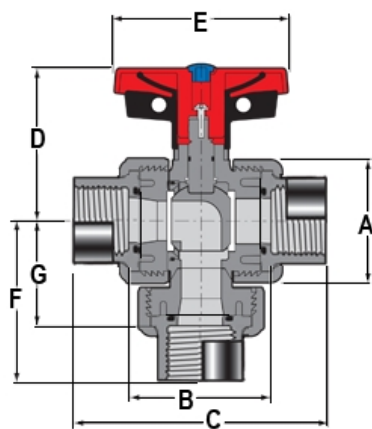

G = 5- 7/8

A = 7- 1/2

B = 7- 1/4

C = 10- 1/4

D = 6- 3/4

E = 9- 3/16

F = 6- 3/4

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

