

Part No: 4731T1-025CSR

Valves

3-Way Ball Valve

Desc: 2-1/2 CPVC TU IND 3WY VRT T/PT SRTHD FKM

MSRP: 2387.89

Part Code: 617

Weight(lbs): 10.212


Weight(kg): 4.632

Weight(gm): 4632

Size: 2-1/2"

Color: GRAY

Material: CPVC

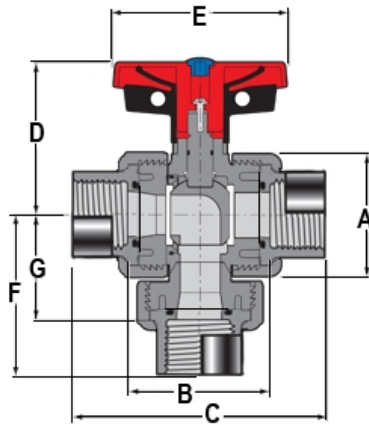

A = 5- 3/8

B = 5- 7/8

C = 8- 1/2

D = 5- 1/8

E = 6- 1/4

F = 5- 1/2

G = 4- 3/8

Type T - Port (Vertical)

Connection SR Fipt

O-Ring FKM

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

