

**Part No:** 4731T1-030CSR

**Valves**

**3-Way Ball Valve**

**Desc:** 3 CPVC T/U IND 3WAY VERT T/PT SR/THD FKM

**MSRP:** 2429.53

**Part Code:** 617

**Weight(lbs):** 10.41


**Weight(kg):** 4.722

**Weight(gm):** 4722

**Size:** 3"

**Color:** GRAY

**Material:** CPVC

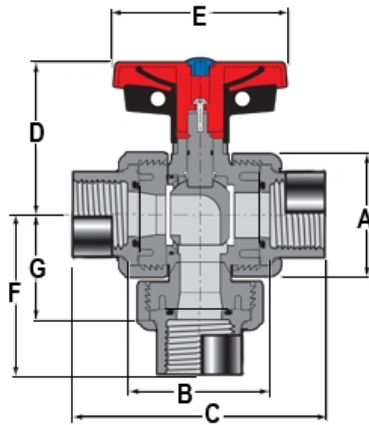

**A** = 6- 3/16

**B** = 6- 7/8

**C** = 9- 3/4

**D** = 5- 7/8

**E** = 7- 5/8

**F** = 6- 3/16

**G** = 4- 7/8

**Type** T - Port (Vertical)

**Connection** SR Fipt

**O-Ring** FKM

## Injection Molded Dimension References:

**G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

**H** = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

**J** = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

**L** = Overall length of fittings; ± 1/16 inch.

**M** = Outside diameter of socket/thread hub; ± 1/16 inch.

**N** = Socket bottom to socket bottom; couplings; ± 1/16 inch.

**W** = Height of cap; ± 1/16 inch

## Typical Molded Dimension References

