

Part No: 4731T1-040SR

Valves

3-Way Ball Valve

Desc: 4 PVC T/U IND 3WAY VERT T/PT SR/THD FKM

MSRP: 2695.98

Part Code: 615

Weight(lbs): 15.759


Weight(kg): 7.148

Weight(gm): 7148

Size: 4"

Color: GRAY

Material: PVC

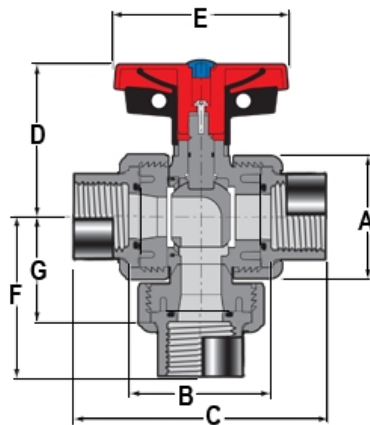

A = 7- 1/2

B = 7- 1/4

C = 10- 1/4

D = 6- 3/4

E = 9- 3/16

F = 6- 3/4

G = 5- 7/8

Type T - Port (Vertical)

Connection SR Fipt

O-Ring FKM

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

