

**Part No:** 4732L3-012C

**Valves**

**3-Way Ball Valve**

**Desc:** 1-1/4 CPVC T/U IND 3WAY VERT L/3 SOC FKM

**MSRP:** 797.11

**Part Code:** 617

**Weight(lbs):** 1.75


**Weight(kg):** 0.794

**Weight(gm):** 794

**Size:** 1-1/4"

**Color:** GRAY

**Material:** CPVC

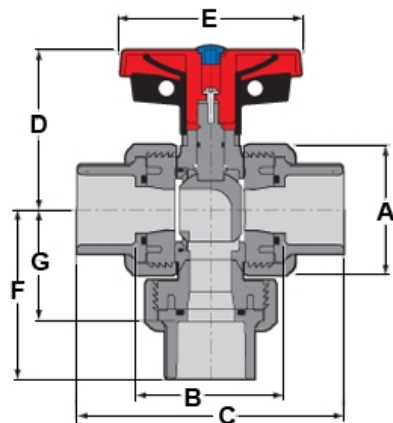

**A** = 3-3/16

**B** = 3-5/16

**C** = 5-13/16

**D** = 3- 5/8

**E** = 3-7/8

**F** = 3- 3/4

**G** = 2-1/2

**Type** Triple L - Port (Vertical)  
**Connection** Socket  
**O-Ring** FKM

## Injection Molded Dimension References:

**G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses;  $\pm 1/32$  inch.

**H** = Intersection of center lines to face of fitting; 90° elbows tees, crosses;  $\pm 1/32$  inch.

**J** = Intersection of center lines to bottom of socket/thread; 45° elbows;  $\pm 1/32$  inch

**L** = Overall length of fittings;  $\pm 1/16$  inch.

**M** = Outside diameter of socket/thread hub;  $\pm 1/16$  inch.

**N** = Socket bottom to socket bottom; couplings;  $\pm 1/16$  inch.

**W** = Height of cap;  $\pm 1/16$  inch

## Typical Molded Dimension References

