

Part No: 4732T1-005C

Valves

3-Way Ball Valve

Desc: 1/2 CPVC T/U IND 3WAY VERT T/PT SOC FKM

MSRP: 285.38

Part Code: 617

Weight(lbs): 0.542


Weight(kg): 0.246

Weight(gm): 246

Size: 1/2"

Color: GRAY

Material: CPVC

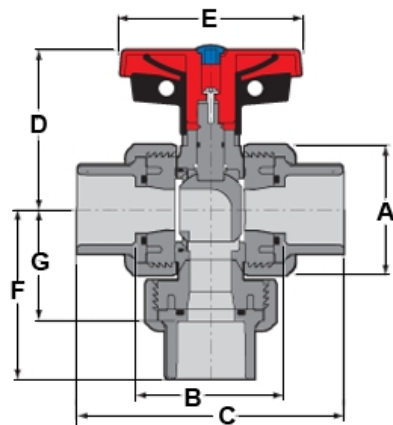

A = 1- 7/8

B = 2- 7/16

C = 4- 3/16

D = 2- 9/16

E = 2-13/16

F = 2- 9/16

G = 1-11/16

Type T - Port (Vertical)

Connection Socket

O-Ring FKM

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

