

Part No: 4733L1-007

Valves

3-Way Ball Valve

Desc: 3/4 PVC T/U IND 3WAY VERT L1 FLG FKM

MSRP: 387.51

Part Code: 615

Weight(lbs): 1.676


Weight(kg): 0.76

Weight(gm): 760

Size: 3/4

Color: GRAY

Material: PVC

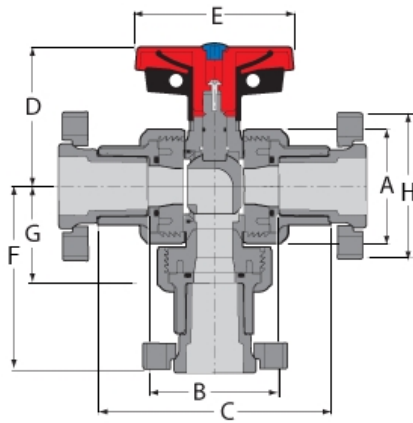

A = 2- 1/4

B = 2- 3/4

C = 4- 3/4

D = 2- 7/8

E = 3- 5/16

G = 2

F = 3-15/16

H = 3-7/8

Type Single L - Port (Vertical)

Connection Flanged

O-Ring FKM

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

