

Part No: 4733L1-010C

Valves

3-Way Ball Valve

Desc: 1 CPVC T/U IND 3WAY VERT L1 FLG FKM

MSRP: 882.96

Part Code: 617

Weight(lbs): 2.361


Weight(kg): 1.071

Weight(gm): 1071

Size: 1

Color: GRAY

Material: CPVC

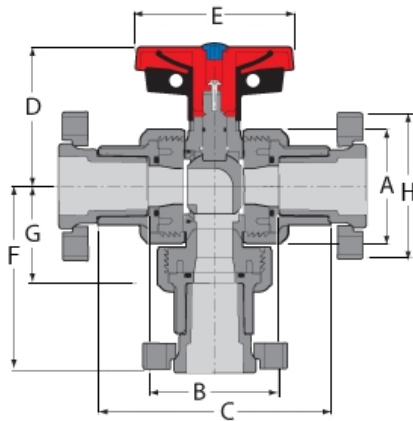

A = 2- 9/16

B = 2- 7/8

C = 5- 1/8

D = 3- 1/8

E = 3- 7/16

G = 2- 1/8

F = 4-15/16

H = 4-1/4

Type Single L - Port (Vertical)

Connection Flanged

O-Ring FKM

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

