

Part No: 4733L1-012C

Valves

3-Way Ball Valve

Desc: 1-1/4 CPVC T/U IND 3WAY VERT L/1 FLG FKM

MSRP: 1626.53

Part Code: 617

Weight(lbs): 2.76


Weight(kg): 1.252

Weight(gm): 1252

Size: 1-1/4

Color: GRAY

Material: CPVC

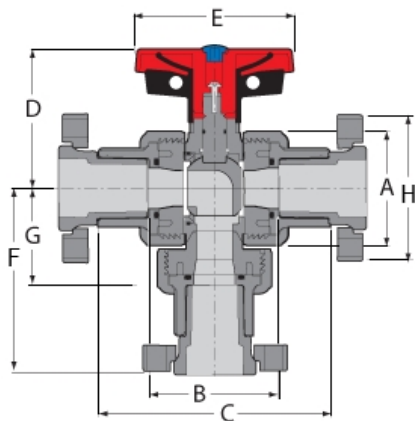

A = 3- 1/16

B = 3- 1/4

C = 5- 3/4

D = 3- 5/8

E = 3-13/16

G = 2- 3/8

F = 4-15/32

H = 4-5/8

Type Single L - Port (Vertical)

Connection Flanged

O-Ring FKM

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

