

Part No: 4733L1-020C

Valves

3-Way Ball Valve

Desc: 2 CPVC T/U IND 3WAY VERT L/I FLG FKM

MSRP: 2146.44

Part Code: 617

Weight(lbs): 7.072


Weight(kg): 3.208

Weight(gm): 3208

Size: 2

Color: GRAY

Material: CPVC

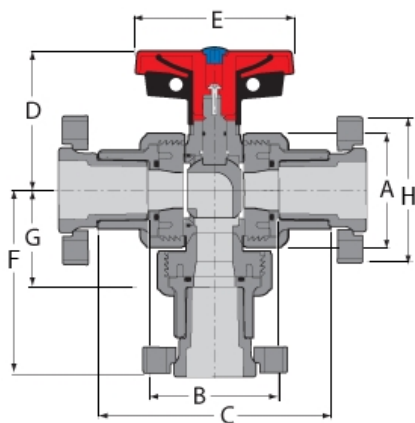

Type Single L - Port (Vertical)

Connection Flanged

O-Ring FKM

A = 4- 1/4

B = 4- 3/4

C = 7- 3/4

D = 4- 1/2

E = 5- 1/8

G = 3- 1/2

F = 6- 3/8

H = 6

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

