

Part No: 4733L2-030

Valves

3-Way Ball Valve

Desc: 3 PVC T/U IND 3WAY VERT L/2 FLG FKM

MSRP: 2915.63

Part Code: 615

Weight(lbs): 15.302


Weight(kg): 6.941

Weight(gm): 6941

Size: 3

Color: GRAY

Material: PVC

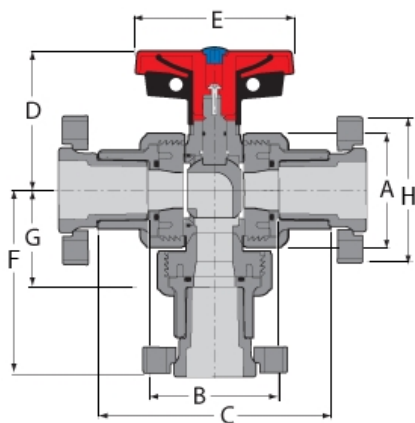

A = 6- 3/16

B = 6- 7/8

C = 10-11/16

D = 5- 7/8

E = 7- 5/8

G = 4- 7/8

No of
Bolts = 4

Bolt = 6
Circle
Dia.

Bolt Size = 5/8

F = 8-1/8

H = 7-1/2

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

