

Part No: 4733L2-040C

Valves

3-Way Ball Valve

Desc: 4 CPVC T/U IND 3WAY VERT L/2 FLG FKM

MSRP: 5819.66

Part Code: 617

Weight(lbs): 26.295


Weight(kg): 11.927

Weight(gm): 11927

Size: 4

Color: GRAY

Material: CPVC

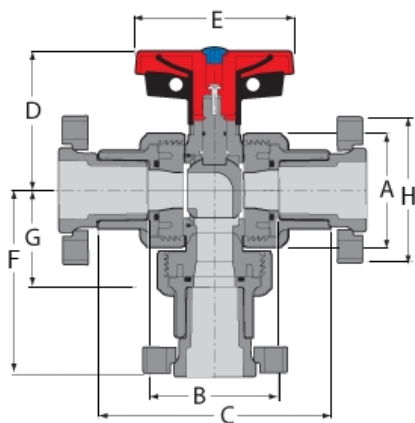

A = 7- 1/2

B = 7- 1/4

C = 11-13/16

D = 6- 3/4

E = 9- 3/16

G = 5- 7/8

No of Bolts = 8

Bolt Circle Dia. = 7- 1/2

Bolt Size = 5/8

F = 8-7/8

H = 9

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

