

Part No: 4733T1-005

Valves

3-Way Ball Valve

Desc: 1/2 PVC T/U IND 3WAY VERT T/PT FLG FKM

MSRP: 366.86

Part Code: 615

Weight(lbs): 1.12


Weight(kg): 0.508

Weight(gm): 508

Size: 1/2

Color: GRAY

Material: PVC

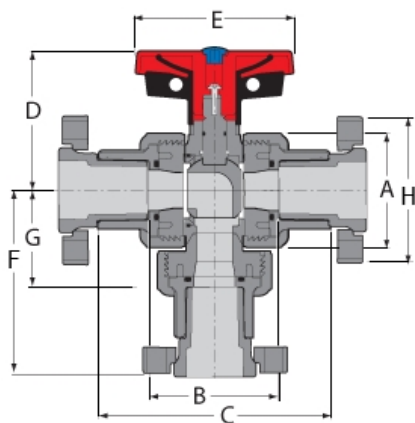

Type T - Port (Vertical)

Connection Flanged

O-Ring FKM

A = 1- 7/8

B = 2- 7/16

C = 4- 3/16

D = 2- 9/16

E = 2-13/16

G = 1-11/16

F = 4-11/32

H = 3-1/2

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

