

Part No: 4733T1-005C

Valves

3-Way Ball Valve

Desc: 1/2 CPVC T/U IND 3WAY VERT T/PT FLG FKM

MSRP: 564.42

Part Code: 617

Weight(lbs): 1.177


Weight(kg): 0.534

Weight(gm): 534

Size: 1/2

Color: GRAY

Material: CPVC

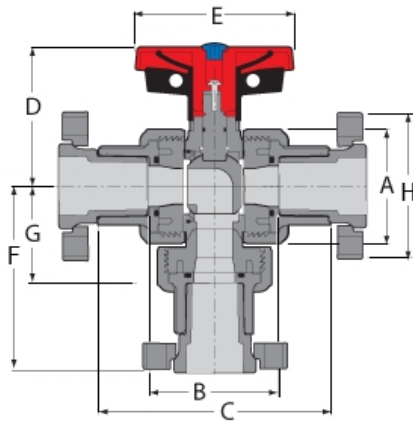

Type T - Port (Vertical)

Connection Flanged

O-Ring FKM

A = 1- 7/8 B = 2- 7/16 C = 4- 3/16 D = 2- 9/16 E = 2-13/16
G = 1-11/16 F = 4-11/32 H = 3-1/2

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

