

Part No: 4733T1-012

Valves

3-Way Ball Valve

Desc: 1-1/4 PVC T/U IND 3WAY VERT T/PT FLG FKM

MSRP: 1057.2

Part Code: 615

Weight(lbs): 3.111


Weight(kg): 1.411

Weight(gm): 1411

Size: 1-1/4

Color: GRAY

Material: PVC

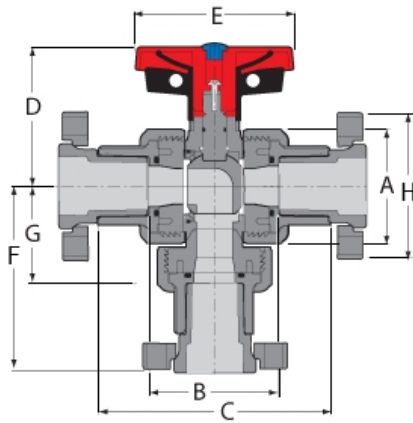

A = 3- 1/16

B = 3- 1/4

C = 5- 3/4

D = 3- 5/8

E = 3-13/16

G = 2- 3/8

F = 4-15/32

H = 4-5/8

Type T - Port (Vertical)

Connection Flanged

O-Ring FKM

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

