

Part No: 4733T1-025C

Valves

3-Way Ball Valve

Desc: 2-1/2 CPVC T/U IND 3WAY VRT T/PT FLG FKM

MSRP: 4196.57

Part Code: 617

Weight(lbs): 14.855


Weight(kg): 6.738

Weight(gm): 6738

Size: 2-1/2

Color: GRAY

Material: CPVC

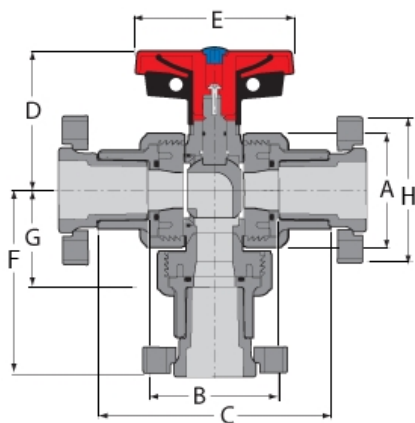

A = 5- 3/8

B = 5- 7/8

C = 9- 5/16

D = 5- 1/8

E = 6- 1/4

G = 4- 3/8

F = 7- 3/16

H = 7- 1/2

Type T - Port (Vertical)

Connection Flanged

O-Ring FKM

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

