

Part No: 4733T1-030C

Valves

3-Way Ball Valve

Desc: 3 CPVC T/U IND 3WAY VERT T/PT FLG FKM

MSRP: 4224.22

Part Code: 617

Weight(lbs): 16.052


Weight(kg): 7.281

Weight(gm): 7281

Size: 3

Color: GRAY

Material: CPVC

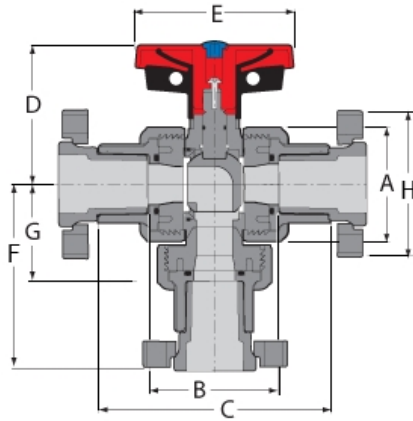

Type T - Port (Vertical)

Connection Flanged

O-Ring FKM

A = 6- 3/16

B = 6- 7/8

C = 10-11/16

D = 5- 7/8

E = 7- 5/8

G = 4- 7/8

F = 8-1/8

H = 7-1/2

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

