

Part No: 4737L1-005C

Valves

3-Way Ball Valve

Desc: 1/2 CPVC T/U IND 3WAY VERT L1 SPG FKM

MSRP: 285.38

Part Code: 617

Weight(lbs): 0.553


Weight(kg): 0.251

Weight(gm): 251

Size: 1/2

Color: GRAY

Material: CPVC

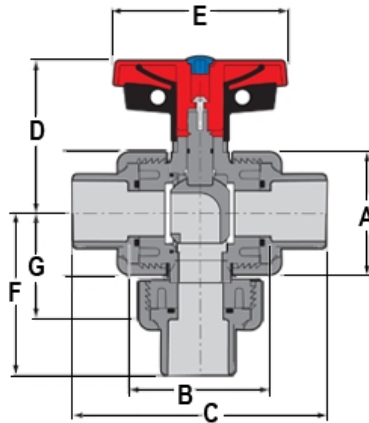

G = 1-11/16

A = 1-7/8

B = 2-7/16

C = 4-3/4

D = 2-9/16

E = 2-13/16

F = 2-13/16

Type Single L - Port (Vertical)
Connection Spigot
O-Ring FKM

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

