

Part No: 4737L1-010

Valves

3-Way Ball Valve

Desc: 1 PVC T/U TU IND 3WAY VERT L/1 SPG FKM

MSRP: 272.04

Part Code: 615

Weight(lbs): 1.105


Weight(kg): 0.501

Weight(gm): 501

Size: 1

Color: GRAY

Material: PVC

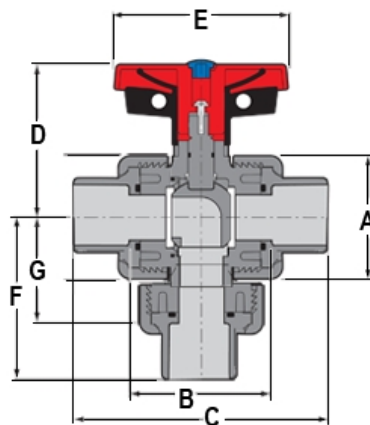

A = 2- 9/16

B = 2- 7/8

C = 5-3/4

D = 3- 1/8

E = 3- 7/16

F = 3-9/16

G = 2- 1/8

Type Single L - Port (Vertical)
Connection Spigot
O-Ring FKM

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

