

Part No: 4737L2-025C

Valves

3-Way Ball Valve

Desc: 2-1/2 CPVC T/U IND 3WAY VERT L/2 SPG FKM

MSRP: 2555.2

Part Code: 617

Weight(lbs): 10.113


Weight(kg): 4.587

Weight(gm): 4587

Size: 2-1/2

Color: GRAY

Material: CPVC

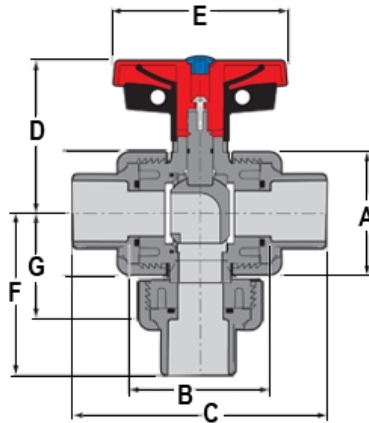

A = 6-3/16

B = 8-1/8

C = 11-5/8

D = 5-7/8

E = 7-5/8

F = 7-1/16

G = 5-5/16

Type Double L - Port (Vertical)
Connection Spigot
O-Ring FKM

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

