

Part No: 4737L2-040C

Valves

3-Way Ball Valve

Desc: 4 CPVC T/U IND 3WAY VERT L/2 SPG FKM

MSRP: 4301.58

Part Code: 617

Weight(lbs): 17.121


Weight(kg): 7.766

Weight(gm): 7766

Size: 4

Color: GRAY

Material: CPVC

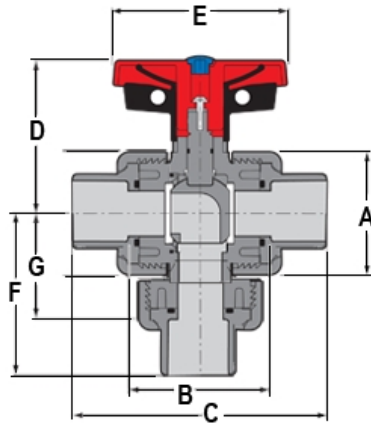

C = 12-13/16

D = 6-3/4

E = 9-3/16

F = 8-3/4

G = 5-7/8

A = 7-1/2

B = 7-1/4

Type Double L - Port (Vertical)
Connection Spigot
O-Ring FKM

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

