

Part No: 4737L3-010

Valves

3-Way Ball Valve

Desc: 1 PVC T/U IND 3WAY VERT L/3 SPG FKM

MSRP: 441.9

Part Code: 615

Weight(lbs): 1.107


Weight(kg): 0.502

Weight(gm): 502

Size: 1

Color: GRAY

Material: PVC

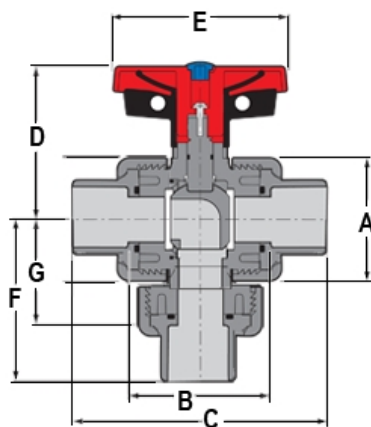

A = 2- 9/16

B = 2- 7/8

C = 5-3/4

D = 3- 1/8

E = 3- 7/16

F = 3-9/16

G = 2- 1/8

Type Triple L - Port (Vertical)
Connection Spigot
O-Ring FKM

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

