

Part No: 4737T1-015C

Valves

3-Way Ball Valve

Desc: 1-1/2 CPVC T/U IND 3WAY VRT T/PT SPG FKM

MSRP: 576.3

Part Code: 617

Weight(lbs): 2.383


Weight(kg): 1.081

Weight(gm): 1081

Size: 1-1/2

Color: GRAY

Material: CPVC

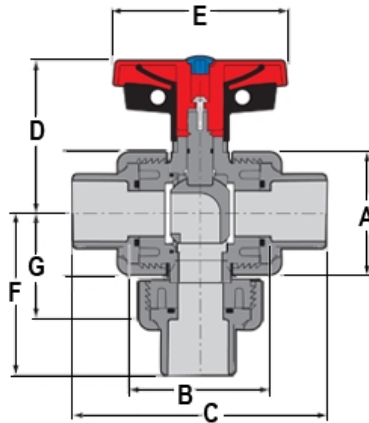


Type T - Port (Vertical)
Connection Spigot
O-Ring FKM

A = 3- 1/2 B = 3- 1/2 C = 6-3/4 D = 4 E = 4- 3/16
 F = 4-1/2 G = 2- 9/16

Injection Molded Dimension References:

- G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.
H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.
J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch
L = Overall length of fittings; $\pm 1/16$ inch.
M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.
N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.
W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

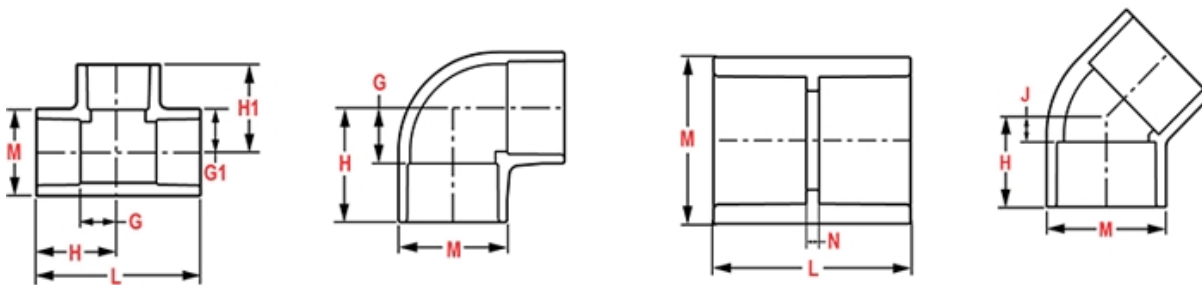

The information printed here is based on current information & product design at the time of publication and is subject to change without notification. Spears® ongoing commitment to product improvement may result in some variation. No representation, guarantees or warranties of any kind are as to its accuracy, suitability for particular application or results to be obtained therefrom. For verification of technical data or additional information, please contact Spears® Technical Service Department :: WEST COAST : (818) 364-1611 - EAST COAST : (717) 938-9006