

Part No: 4737T1-020C

Valves

3-Way Ball Valve

Desc: 2 CPVC T/U IND 3WAY VERT T/PT SPG FKM

MSRP: 748.81

Part Code: 617

Weight(lbs): 5.073


Weight(kg): 2.301

Weight(gm): 2301

Size: 2

Color: GRAY

Material: CPVC

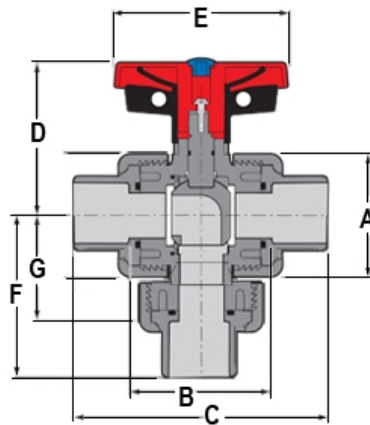

A = 4- 1/4

B = 4- 3/4

C = 8-1/4

D = 4- 1/2

E = 5- 1/8

F = 5-5/16

G = 3- 1/2

Type T - Port (Vertical)

Connection Spigot

O-Ring FKM

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

