

Part No: 474-015

Inserts

Adapter

Desc: 1-1/2 PVC ADAPTER INSERTXSOC SCH40

MSRP: 7.74

Part Code: 040

Weight(lbs): 0.137

Weight(kg): 0.062

Weight(gm): 62


Size: 1-1/2"

Color: WHITE

Material: PVC

Connection Insert x Socket

Type Standard

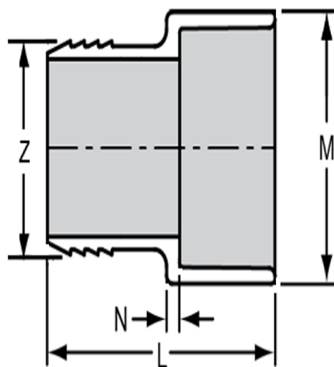

L = 3- 1/16

Z = 1-21/32

M = 2-5/16

N = 5/16

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

