

Part No: 474-030

Inserts

Adapter

Desc: 3 PVC ADAPTER INSERTXSOC SCH40

MSRP: 42.73

Part Code: 040

Weight(lbs): 0.507

Weight(kg): 0.23

Weight(gm): 230


Size: 3"

Color: WHITE

Material: PVC

Connection Insert x Socket

Type Standard

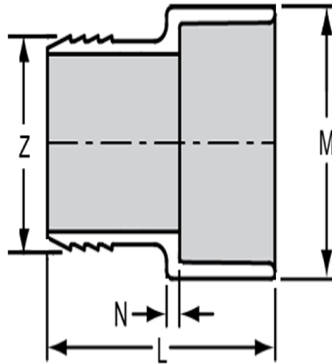

L = 4-3/4

M = 4-1/32

N = 9/32

Z = 3-3/32

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

