

Part No: 475-100

Schedule 40 White

Wye

Desc: 10 PVC WYE SOC SCH40 100PSI

MSRP: 2157.42

Part Code: 041

Weight(lbs): 26.804

Weight(kg): 12.158

Weight(gm): 12158


Size: 10"

Color: WHITE

Material: PVC

Connection Socket x Socket x Socket

Type Standard

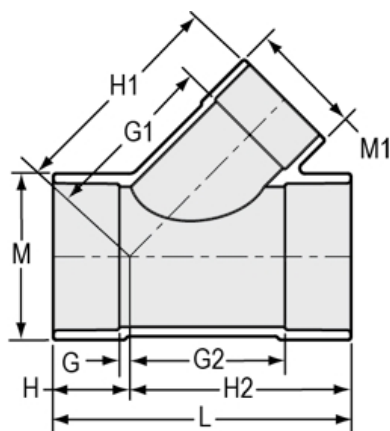

G = 2-17/32

G1 = 13-29/32

G2 = 13-29/32

H = 7-17/32

H1 = 18-29/32

H2 = 18-29/32

L = 26-7/16

M = 11-9/16

M1 = 11-9/16

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

