

Part No: 475-668F

Fabricated Fittings

Wye

Desc: 12X8 PVC RED Y SOC SCH40 100PSI G

MSRP: 1821.1

Part Code: 047

Weight(lbs): 45.572

Weight(kg): 20.671

Weight(gm): 20671

Size: 12"X12"X8"


Color: WHITE

Material: PVC

Schedule SCH 40

Connection Socket X Socket X Socket

Type Reduction

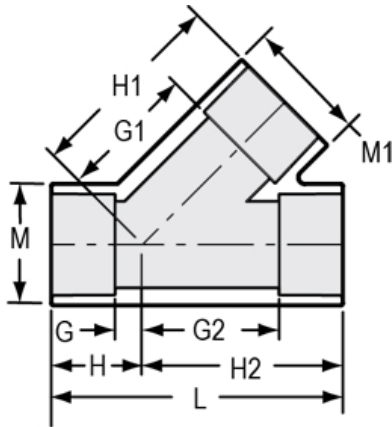

$G = 3 - \frac{7}{8}$	$G1 = 17 - \frac{1}{16}$	$G2 = 16 - \frac{5}{8}$	$H = 10 - \frac{1}{8}$	$H1 = 21 - \frac{5}{16}$
$H2 = 22 - \frac{7}{8}$	$L = 33$	$M = 13 - \frac{9}{16}$	$M1 = 9 - \frac{1}{4}$	

Fabricated Dimension References:

- G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.
- H** = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.
- J** = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.
- L** = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.
- M** = Outside diameter of socket/thread hub; $\pm 1/4$ inch.
- N** = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.
- W** = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

