

Part No: 475-760F

Fabricated Fittings

Wye

Desc: 16X10 PVC RD Y SOC SCH40 100PSI G

MSRP: 3229.99

Part Code: 047

Weight(lbs): 80.094

Weight(kg): 36.33

Weight(gm): 36330

Size: 16"X16"X10"


Color: WHITE

Material: PVC

Schedule SCH 40

Connection Socket X Socket X Socket

Type Reduction

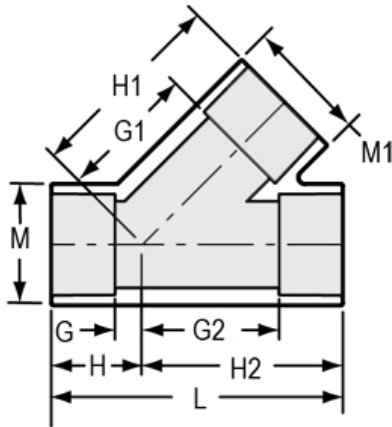

G = 4	G1 = 20- 5/16	G2 = 20	H = 12	H1 = 25- 9/16
H2 = 28	L = 40	M = 17	M1 = 11- 1/2	

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/4 & larger ± 1/2 inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; ± 1/4 inch.; wyes ± 1/2 inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/4 inch; 14" & larger ± 1/2 inch.

L = Overall length of fittings; ± 1/2 inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; ± 1/4 inch.

N = Socket bottom to socket bottom; couplings; ± 1/2 inch.

W = Height of cap; ± 1/4 inch.

Typical Fabricated Dimension References

