

Part No: 475-764F

Fabricated Fittings

Wye

Desc: 16X14 PVC RD Y SOC SCH40 100PSI G

MSRP: 4073.99

Part Code: 047

Weight(lbs): 100.509

Weight(kg): 45.59

Weight(gm): 45590

Size: 16"X16"X14"


Color: WHITE

Material: PVC

Schedule SCH 40

Connection Socket X Socket X Socket

Type Reduction

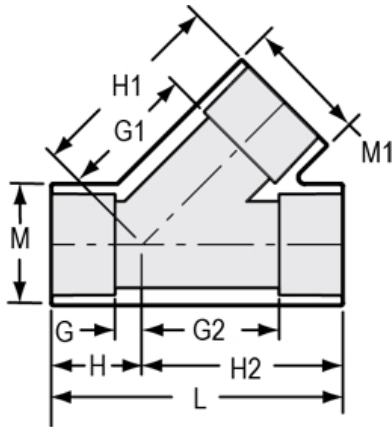

G = 6- 3/8	G1 = 22- 1/2	G2 = 22- 3/8	H = 14- 3/8	H1 = 29- 1/2
H2 = 30- 3/8	L = 44- 3/4	M = 17	M1 = 14- 7/8	

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/4 & larger ± 1/2 inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; ± 1/4 inch.; wyes ± 1/2 inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/4 inch; 14" & larger ± 1/2 inch.

L = Overall length of fittings; ± 1/2 inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; ± 1/4 inch.

N = Socket bottom to socket bottom; couplings; ± 1/2 inch.

W = Height of cap; ± 1/4 inch.

Typical Fabricated Dimension References

