

Part No: 475-781F

Fabricated Fittings

Wye

Desc: 18X2 PVC RED WYE SOC SCH40 100PSI G

MSRP: 2197.88

Part Code: 047

Weight(lbs): 61.399

Weight(kg): 27.85

Weight(gm): 27850

Size: 18 X 2


Color: WHITE

Material: PVC

Schedule SCH 40

Connection Socket X Socket X Socket

Type Reduction

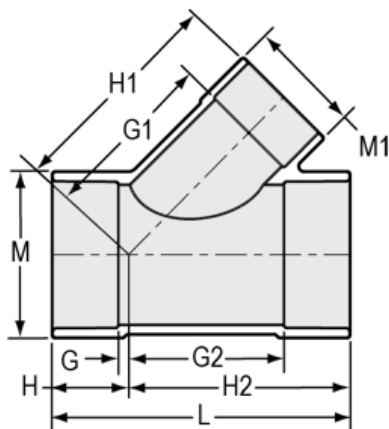

H1 = 17-13/16

H2 = 23-7/8

L = 29-3/4

M = 19-1/8

M1 = 2-11/16

G = 3-1/8

G1 = 16-1/16

G2 = 14-7/8

H = 5-7/8

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

